


Manifold strip

VABM-P6-15MB-G18-M5-6

Part number: 8083546

FESTO

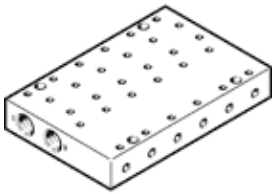

Data sheet

| Feature | Value |
|---|---------------------------------|
| Grid dimension | 15 mm |
| Design structure | Connection direction underneath |
| Max. number of valve positions | 6 |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B2-L |
| Max. tightening torque, valve mounting | 0.6 Nm |
| Product weight | 210 g |
| Pneumatic connection, port 1 | G1/8 |
| Pneumatic connection, port 2 | M5 |
| Materials note | Conforms to RoHS |
| Material manifold | Wrought Aluminum alloy |