


# Coupling

## EAMD-32-32-14-16X20-U

Part number: 8086051

FESTO

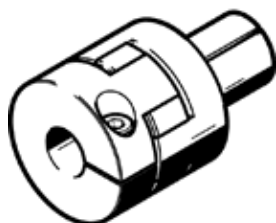

### Data sheet

Feature	Value
Holder diameter 1	14 mm
Holder diameter 2	16 mm
Size	32
Nominal length	32 mm
Assembly position	Any
Max. speed	8,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	14.5 kgmm <sup>2</sup>
Transferable torque	16 Nm
Product weight	124 g
Materials note	Conforms to RoHS