


# Axial kit EAMM-A-V25-42AB

Part number: 8094108

FESTO

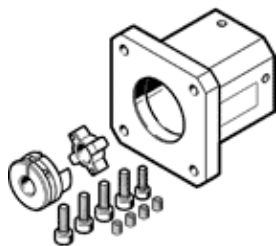

## Data sheet

Feature	Value
Nominal length	36 mm
Assembly position	Any
Max. speed	10,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Mass moment of inertia	0.19 kgmm <sup>2</sup>
Transferable torque	0.5 Nm
Product weight	75 g
Interface code, actuator	V25
Interface code, motor in	42AB
Materials note	Conforms to RoHS