


Exhaust plate

VABF-B14-M3-N14

Part number: 8099627

FESTO

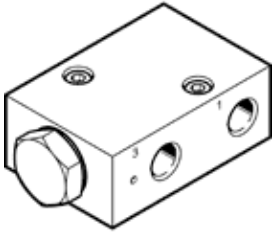

Data sheet

| Feature | Value |
|---|--|
| Assembly position | Any |
| Working pressure | 1.5 ... 10 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364 zone III |
| Storage temperature | -20 ... 80 °C |
| Medium temperature | -20 ... 80 °C |
| Ambient temperature | -20 ... 80 °C |
| Product weight | 280.5 g |
| Mounting type | with through hole |
| Pneumatic connection, port 1 | 1/4 NPT |
| Pneumatic connection, port 2 | Flange 1/4 with NAMUR connection |
| Pneumatic connection, port 4 | Flange 1/4 with NAMUR connection 1/4 NPT |
| Materials note | Conforms to RoHS |
| Material regulator housing | Wrought Aluminum alloy |