


Axial kit

EAMM-A-P4-28B-38AA

Part number: 8107704

FESTO

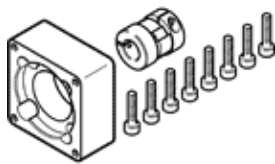

Data sheet

Feature	Value
Assembly position	Any
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Transferable torque	0.7 Nm
Product weight	59 g
Interface code, actuator	P4-28B
Interface code, motor in	38AA
Materials note	Conforms to RoHS