


Axial kit

EAMM-A-P6-38A-60RA

Part number: 8123496

FESTO

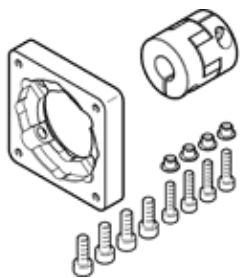

Data sheet

Feature	Value
Assembly position	Any
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Transferable torque	6.5 Nm
Product weight	209 g
Interface code, actuator	P6-38A
Interface code, motor in	60RA
Materials note	Conforms to RoHS