


Power supply unit CACN-3A-1-20-G2

Part number: 8149582

FESTO

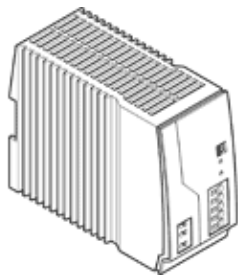

Data sheet

| Feature | Value |
|---|--|
| Width | 68 mm |
| Height | 130 mm |
| Length | 160 mm |
| Assembly position | Free convection |
| Primary supply | Single-phase |
| Input current | 2,4 - 5,6 A |
| Nominal output voltage DC | 24 V |
| Nominal output current | 20 A |
| Input voltage range AC | 100 ... 240 V |
| Power failure buffering | 15 ms |
| Line frequency | 45 ... 65 Hz |
| Authorization | c UL us - Listed (OL) |
| CE symbol (see declaration of conformity) | according to EU-EMV guideline according to EU low voltage guideline |
| PWIS conformity | VDMA24364 zone III |
| Storage temperature | -40 ... 85 °C |
| Relative air humidity | 95 % |
| Protection class | IP20 |
| Ambient temperature | -25 ... 70 °C |
| Product weight | 1,669 g |
| Mounting type | with top-hat rail |
| Materials note | Conforms to RoHS |