


# Connector kit DADG-AK-G8-12-10

Part number: 8152373

FESTO

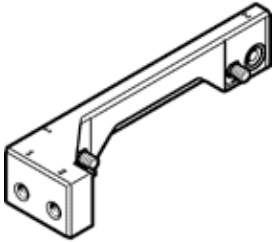

## Data sheet

Feature	Value
Size	12
Stroke	10 mm
Operating pressure MPa	0.1 ... 0.8 MPa
Working pressure	1 ... 8 bar
Operating pressure	14.5 ... 116 psi
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Max. tightening torque	1.5 Nm
Tightening torque tolerance	± 10 %
Max. tightening torque, pneumatic connection 1	0.7 Nm
Product weight	12.2 g
Pneumatic connection	M5
Material adapter	Epoxy resin
Material seals	NBR
Material screws	Coated steel