


End stop limit switch SDK-3-PK-3

Part number: 8714

FESTO

With ball actuator

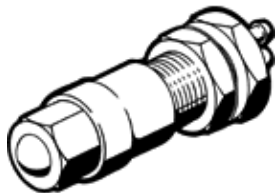

Data sheet

| Feature | Value |
|------------------------------------|---|
| Valve function | 3/2 closed, monostable |
| Type of actuation | mechanical |
| Standard nominal flow rate | 16 l/min |
| Working pressure | 0 ... 8 bar |
| Design structure | Spherical seat |
| Type of reset | mechanical spring |
| Nominal size | 0.6 mm |
| Exhaust-air function | throttleable |
| Sealing principle | soft |
| Type of piloting | direct |
| Flow direction | non reversible |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:4:4] |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| PWIS conformity | VDMA24364-B1/B2-L |
| Medium temperature | -10 ... 80 °C |
| Ambient temperature | -10 ... 80 °C |
| Actuating force | 12 N |
| Product weight | 50 g |
| Mounting type | with through hole |
| Pneumatic connection, port 1 | PK-3 |
| Pneumatic connection, port 2 | PK-3 |
| Pneumatic connection, port 3 | Non-ducted |