


Round cylinder DGS-20- -P

 
Part number: 8805
Product to be discontinued

FESTO

With elastic cushioning rings in end positions
Type to be discontinued. Available until 2016. See Support Portal for alternative products.

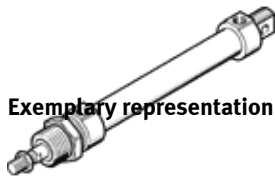

Exemplary representation



Data sheet

| Feature | Value |
|--|---|
| Stroke | 1 ... 500 mm |
| Piston diameter | 20 mm |
| Cushioning | P: Flexible cushioning rings/plates at both ends |
| Position detection | No |
| Variants | Single-ended piston rod |
| Working pressure | 1 ... 10 bar |
| Mode of operation | double-acting |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:4:4] |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| Ambient temperature | -20 ... 80 °C |
| Theoretical force at 6 bar, return stroke | 158 N |
| Theoretical force at 6 bar, advance stroke | 188 N |
| Pneumatic connection | G1/8 |