


Plastic-coated metal tube PM-6

Part number: 9087

FESTO

Suitable for use with QS push-fit fittings.

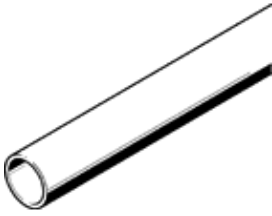

Data sheet

Feature	Value
Outside diameter	8 mm
Bending radius relevant for flow rate	25 mm
Inside diameter	5.2 mm
Temperature dependent working pressure	-0.95 ... 30 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-29 ... 65 °C
Product weight according to length	0.032 kg/m
Color	Black
Materials note	Conforms to RoHS
Material tubing	Wrought Aluminum alloy PE