


# Automation system CPX-E /-EX1E

Broj artikla: 5237644

FESTO

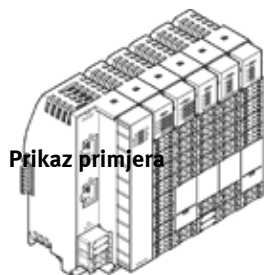

Prikaz primjera

## Tehnički podaci

Skupni list podataka - Pojedinačne vrijednosti ovise o Vašoj konfiguraciji.

Svojstvo	Vrijednost
Električno aktiviranje	Feldbus integrirani kontroler
Mjera rastera	18,9 mm
Vrsta pričvršćenja	sa H - profilom
Maks. broj modula	10
Temperatura okoline	-5 ... 50 °C
Informacija o temperaturi okoline	-5 - 60°C for vertical installation
Temperatura ležaja	-20 ... 70 °C
Relativna vlažnost zraka	95 % ne kondenzira se
Mehanička zaštita	IP20
Klasa korozione otpornosti KBK	0 - bez otpornosti na koroziju
Otpornost na vibracije	Transport application test with severity level 1 as per FN 942017-4 and EN 60068-2-6
Udarne čvrstoća	Shock test with severity level 1 in accordance with FN 942017-5 and EN 60068-2-27
Zaštita od direktnog i indirektnog dodira	Protective extra-low voltage with safe disconnection (PELV)
PWIS conformity	VDMA24364 zone III
CE znak (vidi izjavu o sukladnosti)	prema EU-EMV-smjernici prema EU-Ex-zaštita-smjernica (ATEX) in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK EX instructions To UK RoHS instructions
KC mark	KC-EMV
Dozvola	RCM Mark c UL us - Listed (OL)
Odobrenje Ex-zaštite izvan EU	EPL Gc (GB)
Mjesto izdavanja certifikata	UL E239998
Material housing	PA
Dijagnoza	via bus via LED Module-specific
Maksimalni volumen adrese za ulaze	64 Byte
Maksimalni volumen adrese za izlaze	64 Byte
Interno vrijeme ciklusa	< 1 ms
Nominal operating voltage DC for electronics/sensors	24 V
Permissible voltage fluctuations for electronics/sensors	± 25 %
Maks. opskrba strujom	8 A
Premošćenje ispada mreže	10 ms
Zaštita od zamjene polova	da