


Kontroler SBRD-Q

Broj artikla: 8067301
Proizvod u napuštanju

FESTO

[Tip u napuštanju. Isporučuje se do 2023. Alternativni proizvod vidi Support Portal.](#)

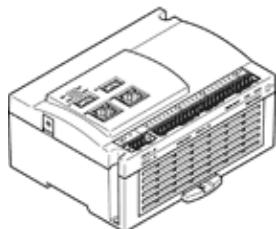

Tehnički podaci

Svojstvo	Vrijednost
Dimenzije Š x D x V	130 mm x 106 mm x 60 mm
Vrsta pričvršćenja	With through-hole for M4 screw sa H - profilom
Težina proizvoda	315 g
KC mark	KC-EMV
CE znak (vidi izjavu o sukladnosti)	prema EU-EMV-smjernici
Zaštita od direktnog i indirektnog dodira	Protective extra-low voltage with safe disconnection (PELV)
Nazivni pogonski napon DC	24 V
Dozvoljena kolebanja napona	+/- 10 %
Primljena snaga 24 V	20 W
Input/output interface, function	10x digital inputs 2x digital inputs with integrated pull-up resistor 8x digital output Ground Opskrba naponom
Input/output interface, type of connection	Utikači
Input/output interface, connection technology	Circuit board plug connector RM 3.5 mm
Input/output interface, number of pins/wires	24
Input/output interface, connection pattern	00995931
Broj ulaza	12
Napomena za ulaze	2 of the 12 inputs with integrated pull-up resistor
Sklopna razina	Signal 1: ≥ 10 V Signal 0: ≤ 1 V
Information on the switching level	Signal 0: ≤ 1 V Signal 1: > 8 V For integrated pull-up resistor
Sklopna logika, ulazi	PNP (plus sklapanje)
Broj izlaza	8
Nazivni pogonski napon DC izlaza	24 V
Digitalni izlazi, izlazna struja	450 mA
Sklopna logika, izlazi	PNP (plus sklapanje)
Power supply, function	Electronics
Napajanje, način spajanja	Utikači
Napajanje, tehnologija spajanja	Circuit board plug connector RM 3.5 mm
Napajanje, broj pinova/žica	4
Camera interface, function	Only communication with camera
Camera interface, connection type	2 x utičnica
Camera interface, connection technology	USB 3.0 type A
Camera interface, number of pins/wires	9
Maks. izlazna struja	1.510 mA
Information on the camera interface	Only use the cables explicitly identified by Festo as accessories
Camera interface, connection pattern	00995870
Ethernet sučelje, protokol	TCP/IP

Svojstvo	Vrijednost
Mrežno sučelje, funkcija	Dijagnoza Programiranje
Mrežno sučelje, način spajanja	Utičnica
Mrežno sučelje, tehnologija spajanja	RJ45
Ethernet sučelje, broj pinova/žica	8
Mrežno sučelje, brzina prijenosa	10 Mbit/s 100 Mbit/s 1000 Mbit/s
Storage medium	microSD
Kapacitet memorije	≤ 32.000.000.000 Byte
Temperatura ležaja	-20 ... 70 °C
Mehanička zaštita	IP20
Temperatura okoline	-5 ... 50 °C
Relativna vlažnost zraka	95 % ne kondenzira se
PWIS conformity	VDMA24364-B2-L
Material housing	PA ojačan
Materijal - napomena	RoHS sukladno