


# Vakuumski filter

## OAFF-G3-7

Broj artikla: 8068945

FESTO

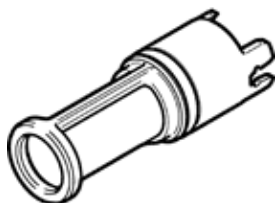

## Tehnički podaci

Svojstvo	Vrijednost
Finoća filtra	40 µm
Veličina pakiranja	10
Operating pressure MPa	-95 ... 0 kPa
Pogonski tlak	-0,95 ... 0 bar
Operating pressure	-13,775 ... 0 psi
Pogonski medij	atmosferski zrak na osnovi ISO 8573-1:2010 [7:-:-]
PWIS conformity	VDMA24364-B1/B2-L
Težina proizvoda	1,5 g
Vrsta pričvršćenja	podizno s uskakanjem
Materijal - napomena	RoHS sukladno
Material seals	NBR
Material filter	Tkanina PA
Material housing	POM
Ejector pulse suitability	0,7 MPa
Prikladnost za impuls odbacivanja	7 bar
Ejector pulse suitability (psi)	101,5 psi