 



Ventil VOFC-L-M52-M-FN14-FN

Broj artikla: 8122930

FESTO

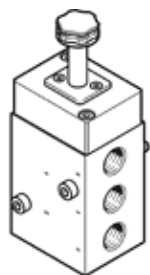

Tehnički podaci

Svojstvo	Vrijednost
Operating pressure MPa	0,25 ... 0,8 MPa
Pogonski tlak	2,5 ... 8 bar
Mehanička zaštita	IP65
Safety Integrity Level (SIL)	Product can be used in SRP/CS up to SIL 2 (high demand) Proizvod se može primijeniti u SRP/CS do SIL 2 niska potreba
Klasa korozione otpornosti KBK	4 - vrlo visoka otpornost na koroziju
PWIS conformity	VDMA24364 zone III
Materijal - napomena	RoHS sukladno