


# Gripper cu ventuza ESG-40

Cod: 189175

FESTO

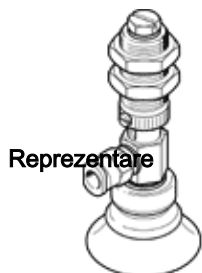

## Fisa tehnica

Fisa date generala - valorile individuale depind de configuratia Dvs.

Caracteristica	valoare
Diametru ventuza	40 mm
pozitie instalare	vertical
Caracteristici speciale	Antistatic
Structura constructiva	racord de vacuum sus racord de vacuum lateral cu compensare a inaltimii cu compensator lung de inaltime
Atribuire suport de ventuza	marimea 4
Forma ventuza	rotund plat rotund adanc rotund, foarte adanc Rotund, burduf 1,5 pliuri rotund, burduf 3,5 pliuri
mediu de operare	Aer atmosferic conform ISO 8573-1:2010 [7:-:-]
Clasa de rezistenta la coroziune KBK	1 - Rezistenta redusa la coroziune
Temperatura mediului	-30 ... 200 °C
Racord de vacuum	M14x1 G1/8 QS-6 PK-4
Indicatie material	conform RoHS
Materialul ventuzei	BR FPM NBR PUR VMQ (silicon) Vulkollan®