


# Gripper cu ventuza ESG-8X20

Cod: 189186

FESTO

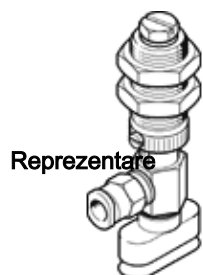

## Fisa tehnica

Fisa date generala - valorile individuale depind de configuratia Dvs.

Caracteristica	valoare
Marime ventuza	8x20 mm
pozitie instalare	vertical
Structura constructiva	racord de vacuum sus racord de vacuum lateral cu compensare a inaltimei cu compensator lung de inaltime
Atribuire suport de ventuza	marimea 4
Forma ventuza	Oval, plat
mediu de operare	Aer atmosferic conform ISO 8573-1:2010 [7:-:-]
Clasa de rezistenta la coroziune KBK	1 - Rezistenta redusa la coroziune
Temperatura mediului	-10 ... 70 °C
Racord de vacuum	M14x1 G1/8 QS-6 PK-4
Indicatie material	conform RoHS
Materialul ventuzei	NBR