


# Gripper cu ventuza ESG-20X60

Cod: 189190

FESTO

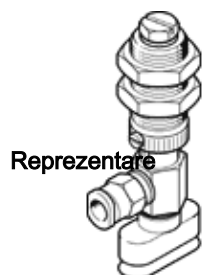

## Fisa tehnica

Fisa date generala - valorile individuale depind de configuratia Dvs.

Caracteristica	valoare
Marime ventuza	20x60 mm
pozitie instalare	vertical
Structura constructiva	racord de vacuum sus racord de vacuum lateral cu compensare a inaltimii cu compensator lung de inaltime
Atribuire suport de ventuza	marimea 5
Forma ventuza	Oval, plat
mediu de operare	Aer atmosferic conform ISO 8573-1:2010 [7:-:-]
Clasa de rezistenta la coroziune KBK	1 - Rezistenta redusa la coroziune
Temperatura mediului	-10 ... 70 °C
Racord de vacuum	G1/8 G1/4
Indicatie material	conform RoHS
Materialul ventuzei	NBR