


Gripper cu ventuza ESG-25X75

Cod: 189191

FESTO

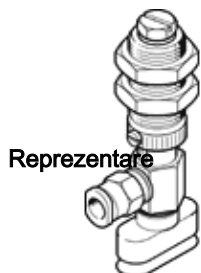

Fisa tehnica

Fisa date generala - valorile individuale depind de configuratia Dvs.

Caracteristica	valoare
Marime ventuza	25x75 mm
pozitie instalare	vertical
Structura constructiva	racord de vacuum sus racord de vacuum lateral cu compensare a inaltimei cu compensator lung de inaltime
Atribuire suport de ventuza	marimea 5
Forma ventuza	Oval, plat
mediu de operare	Aer atmosferic conform ISO 8573-1:2010 [7:-:-]
Clasa de rezistenta la coroziune KBK	1 - Rezistenta redusa la coroziune
Temperatura mediului	-10 ... 70 °C
Racord de vacuum	G1/8 G1/4
Indicatie material	conform RoHS
Materialul ventuzei	NBR