 



Ventil electromagnetic MFHB-2-1/4-B

Cod: 546064

FESTO

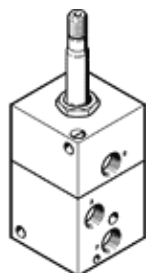

Fisa tehnica

Caracteristica	valoare
functie ventil	2/2 inchis, monostabil
tip de actionare	electric
Debit nominal	600 l/min
presiune de operare	2 ... 8 bar
Structura constructiva	scaun tip taler
Tip de revenire	arcuri mecanice
Tip de protectie	IP65
Deschidere nominala	7 mm
pozitie instalare	Oricare
Actionare manuala auxiliara	cu retinere
Durata de deconectare	23 ms
Durata de conectare	12 ms
Clasa de rezistenta la coroziune KBK	2 - Rezistenta moderata la coroziune
Conformitatea PWIS	VDMA24364-B1/B2-L
Temperatura medie	-10 ... 60 °C
Temperatura mediului	-5 ... 40 °C
Greutate produs	575 g
Racord exhaustare aer de comanda 84	M5
Conexiune pneumatica 1	G1/4
Conexiune pneumatica 2	G1/4
Materialul etansarilor	NBR
Materialul carcasei	Aluminiu eloxat