


**racord cu fisa**  
**QS-F-14-10**  
Cod: 570433

**FESTO**

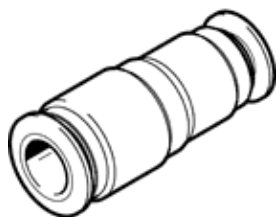

**Fisa tehnica**

<b>Caracteristica</b>	<b>valoare</b>
marime de fabricatie	standard
deschidere nominala	9 mm
structura constructiva	principiu Push-Pull
Operating pressure complete temperature range	-0,95 ... 16 bar
mediu de operare	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
clasa de rezistenta la coroziune KBK	3
Food safety	to manufacturer's declaration
temperatura mediului	0 ... 150 °C
aprobare	Germanischer Lloyd
greutate produs	68 g
racord pneumatic 1	For tubing outside diameter 14 mm
racord pneumatic 2	pentru furtun cu diametru exterior 10 mm
indicatie material	conform RoHS
informatii referitoare la material pentru carcasa	alama cromat si nichelat
informatii referitoare la material pentru etansare furtun	FPM