


# Racord rapid QS-F-G1/2-14H

Cod: 570438

FESTO

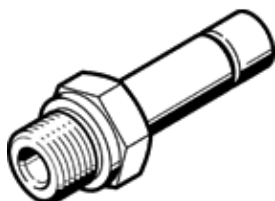

## Fisa tehnica

| Caracteristica   | valoare  |
|--|--|
| marime de fabricatie                                     | standard   |
| deschidere nominala                                      | 12 mm  |
| tip de etansare la fusul cu insurubare                   | inel de etansare   |
| structura constructiva                                   | principiu Push-Pull                                      |
| Operating pressure complete temperature range            | -0,95 ... 16 bar   |
| mediu de operare   | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium                       | Lubricated operation possible                            |
| clasa de rezistenta la coroziune KBK                     | 3  |
| Food safety  | to manufacturer's declaration                            |
| temperatura mediului                                     | 0 ... 150 °C   |
| aprobare   | Germanischer Lloyd                                       |
| cuplul maxim de pornire                                  | 40 Nm  |
| greutate produs  | 34 g   |
| racord pneumatic 1                                       | G1/2   |
| racord pneumatic 2                                       | For tubing outside diameter 14 mm                        |
| indicatie material                                       | conform RoHS   |
| informatii referitoare la material pentru carcasa        | alama<br>cromat si nichelat                              |
| informatii referitoare la material pentru etansare filet | FPM  |