


Portal liniar DHSL-4-DGC40S-DGSL16

Cod: 574509

FESTO

Pentru a obtine o oferta, va rugam apasati simbolul cerere FAX.

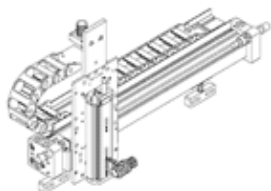

Fisa tehnica

Caracteristica	valoare
Asamblare	Portal 4
Incarcatura efectiva	0 ... 4 kg
Unitate de actionare, axa Z	DGSL-16
Sistem de actionare, axa Z	pneumatic
Cursa, axa Z	0 ... 150 mm
Acuratete de repetare in pozitia de capat, axa Z	$\pm 0,01$ mm
Unitate de actionare, axa Y	DGC-40
Sistem de actionare, axa Y	pneumatic
Pozitie intermediara, axa Y	x 1
Cursa, axa Y	0 ... 8.500 mm
Acuratete de repetare in pozitia de capat, axa Y	$\pm 0,02$ mm
Acuratete de repetare in pozitia intermediara, axa Y	$\pm 0,02$ mm