


# Portal liniar DHSL-10-DGC32FAS-DGSL25

Cod: 574524

FESTO

Pentru a obtine o oferta, va rugam apasati simbolul cerere FAX.

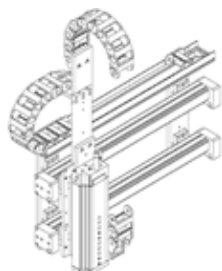

## Fisa tehnica

Caracteristica	valoare
Asamblare	Portal 10
Incarcatura efectiva	0 ... 10 kg
Unitate de actionare, axa Z	DGSL-25
Sistem de actionare, axa Z	pneumatic
Cursa, axa Z	0 ... 200 mm
Acuratete de repetare in pozitia de capat, axa Z	$\pm 0,01$ mm
Unitate de actionare, axa Y	DGC-32-FA
Sistem de actionare, axa Y	pneumatic
Pozitie intermediara, axa Y	x 1
Cursa, axa Y	0 ... 8.500 mm
Acuratete de repetare in pozitia de capat, axa Y	$\pm 0,02$ mm
Acuratete de repetare in pozitia intermediara, axa Y	$\pm 0,02$ mm