


# Interfata bus CDPX-F-CO

Cod: 575301

FESTO

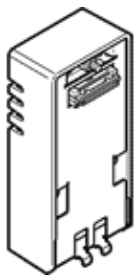

## Fisa tehnica

Caracteristica	valoare
adancimea de montare	24 mm
Inaltime	91 mm
Lungime	41 mm
Aprobare	C-Tick c UL us - Listed (OL)
Simbol CE (vezi declaratia de conformitate)	conform directivei europene EMV in conformitate cu directivele EU RoHS
Marcaj UKCA (a se vedea declaratia de conformitate)	conform reglementărilor UK privind EMC conform reglementarilor UK RoHS
Conformitatea PWIS	VDMA24364-zona III
Temperatura de depozitare	-20 ... 70 °C
Umiditatea relativa a aerului	5 - 85 % nu condenseaza
Tip de protectie	IP20
Temperatura mediului	0 ... 50 °C
Greutate produs	150 g
Indicatie material	conform RoHS
Interfata Fieldbus	CANopen
Interfata Fieldbus, tehnologie de conectare	stecher Sub-D 9 pini
interfata fieldbus, rata transmitere	9,6 kbit/s bis 1 Mbit/s