


Kit axial EAMM-A-L48-120GA

Cod: 8063490

FESTO

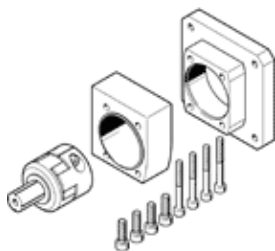

Fisa tehnica

Caracteristica	valoare
pozitie instalare	Oricare
Conformitatea PWIS	VDMA24364-B2-L
Temperatura de depozitare	-25 ... 60 °C
Umiditatea relativa a aerului	0 - 95 %
Tip de protectie	IP40
Temperatura mediului	-10 ... 60 °C
Moment de rotatie transferabil	17 Nm
Greutate produs	705 g
Cod interfata actuator	L48
Cod interfata, intrare motor	120GA
Indicatie material	conform RoHS