


# Bobina VACC-S13-18-K4-1U-NM4ME

Cod: 8118324

FESTO

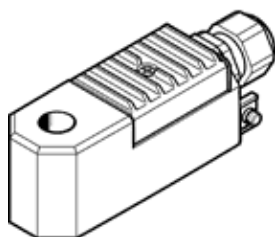

## Fisa tehnica

Caracteristica	valoare
tip de actionare	electric
pozitie instalare	Oricare
Afisarea pozitiei de comutare	nu
Durata de anclansare	100 %
Clasa izolatie	H
Caracteristica bobina	24 V DC: 1.8 W 24 V AC: 40/65 Hz, putere 1.8 VA
Oscilatii admisibile ale tensiunii	-15 % / +10 %
Certificat ATEX in afara UE	EPL Db (BR) EPL Gb (BR)
Departament eliberare certificate	INMETRO DNV 17.0042X
Tip gaz cu protectie la explozie si aprindere	Ex eb mb IIC T6, T5, T4 Gb
Tip praf cu protectie la aprindere si explozie	ExtbIIICT85°C,T95°C,T130°C Db
Protectie la explozie temperatura ambientala	T4,T130°C: -30°C ≤ Ta ≤ +60°C T5,T95°C: -30°C ≤ Ta ≤ +60°C T6,T85°C: -30°C ≤ Ta ≤ +50°C
Conformitatea PWIS	VDMA24364-zona III
Tip de protectie	IP65
Greutate produs	330 g
Conectare electrica	Cutie terminal, cablu filetat M20x1.5
Indicatie material	conform RoHS