


# Y型插入接頭 CRQSY-8

料號: 130658

FESTO

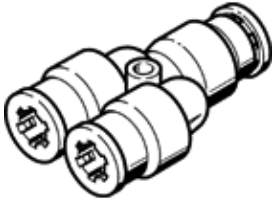

## 技術參數

特性	值
尺寸	標準
額定尺寸	4.9 mm
裝配位置	任何
設計	Y-shape
容器尺寸	1
設計結構	推/拉原理
Operating pressure for entire temperature range	-0.095 ... 1 MPa
操作壓力的完整溫度範圍	-0.95 ... 10 bar
Operating pressure for entire temperature range	-13.775 ... 145 psi
操作壓力注意事項	Water: max. 0.6 MPa at max. 50°C
操作介質	壓縮空氣符合 ISO8573-1:2010 [7:-:-] Water (liquid, free of ice)
注意: 操作和嚮導介質	潤滑操作可行
耐腐蝕等級 CRC	4 - Very high corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Food-safe	See Supplementary material information
環境溫度	-15 ... 120 °C
產品重量	34 g
輸出數量	2
輸送管線的數量	1
可使用電線	PFAN
氣壓連接, 氣口 1	For tubing outside diameter 8 mm
氣壓連接, 氣口 2	For tubing outside diameter 8 mm
材料備註	符合 RoHS
Material housing	高合金鋼, 耐腐蝕
Material release ring	高合金鋼, 耐腐蝕
Material of tubing seal	FPM
Material of tube retaining claw	高合金鋼, 耐腐蝕
Thrust ring material	高合金鋼, 耐腐蝕