

馬達電纜

 

NEBM-S1W15-E-10-Q7-LE6

料號: 1450947

★ Kernprogramm

適用於伺服馬達EMMS-ST...

FESTO

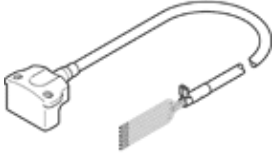

技術參數

| 特性 | 值 |
|--|--------------------------------------|
| Cable identification | Without inscription label holder |
| Electrical connection 1, function | Field device side |
| Electrical connection 1, design | 有角的 |
| Electrical connection 1, connection type | 插頭插座 |
| Electrical connection 1, cable outlet | Angled |
| Electrical connection 1, connection technology | Sub-D |
| Electrical connection 1, number of pins/wires | 15 |
| Electrical connection 1, occupied pins/wires | 10 |
| Electrical connection 2, function | Controller side |
| Electrical connection 2, connection type | 電纜 |
| Electrical connection 2, connection technology | 開放式終端 |
| Electrical connection 2, number of pins/wires | 6 |
| Electrical connection 2, occupied pins/wires | 6 |
| 工作電壓範圍 DC | 0 ... 72 V |
| 額定工作電壓 DC | 24 V |
| 電纜長度 | 10 m |
| 電纜屬性 | Suitable for energy chains |
| Bending radius, flexible cable installation | >= 80 mm |
| 電纜直徑 | 8 mm |
| 電纜結構 | 6x0,75 已屏蔽 |
| 導體的額定截面 | 0.75 mm ² |
| 導線末端 | 導線末端套圈 |
| 防護等級 | IP65 |
| Note on degree of protection | 裝配狀態 |
| 環境溫度 | -40 ... 80 °C |
| Ambient temperature with flexible cable installation | -5 ... 80 °C |
| CE 符號 (參見符合的標準) | in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK RoHS instructions |
| PWIS conformity | VDMA24364-B2-L |
| 材料備註 | 符合 RoHS |
| 耐腐蝕等級 CRC | 0 - No corrosion stress |
| Material cable sheath | TPE-U(PUR) |
| 電纜外套顏色 | 灰色 |