


L型快插式螺紋接頭

QSL-V0-1/8-8

料號: 160512

FESTO

360° orientable, male thread with external hexagon.

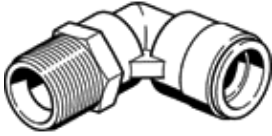

技術參數

| 特性 | 值 |
|---|--|
| 尺寸 | 標準 |
| 額定尺寸 | 6 mm |
| Material fire test | UL94 V-0 (housing) UL94 V-0 (releasing ring) |
| 柱頭螺柱上的密封件類型 | 外表層 |
| 設計 | L-shape |
| 容器尺寸 | 10 |
| 設計結構 | 推/拉原理 |
| Operating pressure for entire temperature range | -0.095 ... 1 MPa |
| 操作壓力的完整溫度範圍 | -0.95 ... 10 bar |
| Operating pressure for entire temperature range | -13.775 ... 145 psi |
| 操作壓力注意事項 | Water: max. 0.6 MPa at max. 50°C |
| 操作介質 | 壓縮空氣符合 ISO8573-1:2010 [7:-:-] Water (liquid, free of ice) |
| 注意: 操作和嚮導介質 | 潤滑操作可行 |
| 耐腐蝕等級 CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| 環境溫度 | 0 ... 60 °C |
| 額定鎖緊扭矩 | 7 Nm |
| 額定擰緊扭矩公差 | ± 20 % |
| 產品重量 | 15 g |
| 安裝類型 | External hex A/F 12 |
| 氣壓連接, 氣口 1 | 外螺紋 R1/8 |
| 氣壓連接, 氣口 2 | For tubing outside diameter 8 mm |
| 釋放環的顏色 | 黑色 |
| Material of threaded plug | 鍍鎳黃銅 |
| 材料備註 | 符合 RoHS |
| Material housing | PBT |
| Material release ring | PBT |
| Material of tubing seal | NBR |
| Material of tube retaining claw | 高合金鋼, 耐腐蝕 黃銅 |