


# 插入連接件

## QS-V0-6

料號: 160546

FESTO

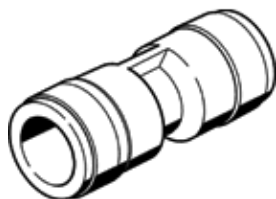

### 技術參數

特性	值
尺寸	標準
額定尺寸	4.3 mm
Material fire test	UL94 V-0 (housing) UL94 V-0 (releasing ring)
設計	直式結構
容器尺寸	10
設計結構	推/拉原理
Operating pressure for entire temperature range	-0.095 ... 1 MPa
操作壓力的完整溫度範圍	-0.95 ... 10 bar
Operating pressure for entire temperature range	-13.775 ... 145 psi
操作壓力注意事項	Water: max. 0.6 MPa at max. 50°C
操作介質	壓縮空氣符合 ISO8573-1:2010 [7:-:-] Water (liquid, free of ice)
注意: 操作和嚮導介質	潤滑操作可行
耐腐蝕等級 CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
環境溫度	0 ... 60 °C
產品重量	7.8 g
氣壓連接, 氣口 1	For tubing outside diameter 6 mm
氣壓連接, 氣口 2	For tubing outside diameter 6 mm
釋放環的顏色	黑色
材料備註	符合 RoHS
Material housing	PBT
Material release ring	PBT
Material of tubing seal	NBR
Material of tube retaining claw	高合金鋼, 耐腐蝕 黃銅