


# 聯合螺栓 MCK-PK-4-KU

料號: 211291

FESTO

聚合物結構.

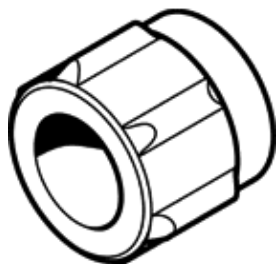

## 技術參數

| 特性  | 值   |
|---|---|
| 尺寸  | 內螺紋 M10x1   |
| Operating pressure for entire temperature range | 0 ... 1 MPa   |
| 操作壓力的完整溫度範圍                                     | 0 ... 10 bar  |
| Operating pressure for entire temperature range | 0 ... 145 psi   |
| PWIS conformity                                 | VDMA24364-B2-L  |
| 環境溫度  | -10 ... 60 °C   |
| 氣壓連接, 氣口 1                                      | For tubing outside diameter 6 mm<br>用於倒鉤接頭內徑 4 mm 具螺母 |
| Material of union nut                           | POM   |
| 材料備註  | 符合 RoHS   |