


編碼器電纜

NEBM-M12W8-E-15-N-R3G8

料號: 5213426
將停止供貨的產品

FESTO

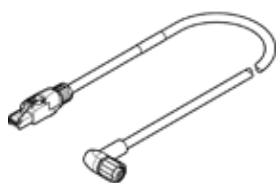

技術參數

| 特性 | 值 |
|--|--|
| Cable identification | Without inscription label holder |
| 產品重量 | 765 g |
| Electrical connection 1, function | Field device side |
| Electrical connection 1, design | 圓形 |
| Electrical connection 1, connection type | 插頭插座 |
| Electrical connection 1, cable outlet | Angled |
| Electrical connection 1, connection technology | M12x1, A-coded in accordance with EN 61076-2-101 |
| Electrical connection 1, number of pins/wires | 8 |
| Electrical connection 1, occupied pins/wires | 8 |
| Electrical connection 2, function | Controller side |
| Electrical connection 2, design | 有角的 |
| Electrical connection 2, connection type | 插頭 |
| Electrical connection 2, cable outlet | 直的 |
| Electrical connection 2, connection technology | RJ45 |
| Electrical connection 2, number of pins/wires | 8 |
| Electrical connection 2, occupied pins/wires | 8 |
| 工作電壓範圍 DC | 0 ... 30 V |
| 額定工作電壓 DC | 24 V |
| 工作電壓範圍 AC | 0 ... 30 V |
| 額定工作電壓, AC | 24 V |
| Note on acceptable current load at 40°C | 2 A for 0.14 mm ² |
| 電纜長度 | 15 m |
| 電纜屬性 | 適合於拖鏈 |
| Bending radius, flexible cable installation | >= 48 mm |
| 電纜直徑 | 5.8 mm |
| 電纜結構 | 1x4x0,15+4x0,34 已屏蔽 |
| 導體的額定截面 | 0.15 mm ² 0.34 mm ² |
| 防護等級 | IP65 |
| Note on degree of protection | IP30 for plug connector Sub-D 裝配狀態 |
| 環境溫度 | -40 ... 80 °C |
| Ambient temperature with flexible cable installation | -10 ... 80 °C |
| CE 符號 (參見符合的標準) | in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK RoHS instructions |
| PWIS conformity | VDMA24364 zone III |
| 材料備註 | 符合 RoHS |
| Material cable sheath | TPE-U(PUR) |