


I/O模組 CP-A04-M12-CL

料號: 538790
將停止供貨的產品

具 4 個輸出

FESTO

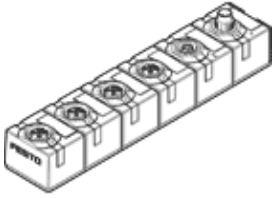

技術參數

特性	值
耐腐蝕等級 CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B2-L
CE 符號 (參見符合的標準)	根據 EU-EMV 指導原則 根據 EU-Ex 防爆指導原則 (ATEX) in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK EX instructions To UK RoHS instructions
KC mark	KC-EMV
授權	RCM Mark c UL us - Listed (OL)
ATEX(防爆) 標準-氣體	II 3G
ATEX(防爆) 標準-灰塵	II 3D
EU以外的防爆保護認證	EPL Dc (GB) EPL Gc (GB)
防氣爆	Ex ec IIC T6 Gc X
防塵爆	Ex tc IIIC T70°C IP67 Dc X
周遭防爆溫度	-5°C ≤ Ta ≤ +50°C