

電源電纜

KPWR-MC-1-SUB-15HC-2,5

 

料號: 538914

將停止供貨的產品

用於為負載和邏輯部件提供電源連接

Type to be discontinued. Available until 2020. See Support Portal for alternative products.

FESTO

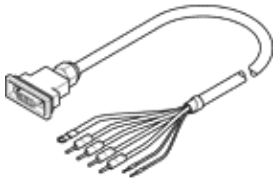

技術參數

特性	值
Cable identification	Without inscription label holder
Electrical connection 1, function	Field device side
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭插座
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	Sub-D Mixed
Electrical connection 1, number of pins/wires	7
Electrical connection 1, occupied pins/wires	6
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	電纜
Electrical connection 2, connection technology	開放式終端
Electrical connection 2, number of pins/wires	6
Electrical connection 2, occupied pins/wires	6
工作電壓範圍 DC	0 ... 24 V
電纜長度	2.5 m
電纜屬性	適合於拖鏈
Bending radius, fixed cable installation	≥ 50 mm
Bending radius, flexible cable installation	≥ 100 mm
電纜直徑	10 mm
電纜結構	2x2,5+2x(2x0,34) 已屏蔽
導體的額定截面	0.34 mm ² 2.5 mm ²
導線末端	Pin terminal
防護等級	IP54
Note on degree of protection	裝配狀態
環境溫度	0 ... 40 °C
Ambient temperature with flexible cable installation	-25 ... 60 °C
材料備註	含有 PWIS
耐腐蝕等級 CRC	0 - No corrosion stress
Material cable sheath	TPE-U(PUR)
Material insulation	TPE-E