

嚮導管路

KES-MC-1-SUB-15-5

 

料號: 538920

將停止供貨的產品

用於 I/O 耦合，以連接至任何控制系統。

Type to be discontinued. Available until 2020. See Support Portal for alternative products.

FESTO

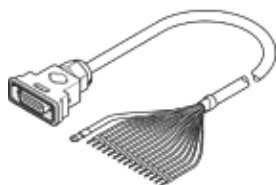

技術參數

特性	值
Cable identification	Without inscription label holder
Electrical connection 1, function	Field device side
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭插座
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	15
Electrical connection 1, occupied pins/wires	15
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	電纜
Electrical connection 2, connection technology	開放式終端
Electrical connection 2, number of pins/wires	18
Electrical connection 2, occupied pins/wires	15
工作電壓範圍 DC	0 ... 24 V
電纜長度	5 m
電纜屬性	適合於拖鏈
Bending radius, fixed cable installation	≥ 40 mm
Bending radius, flexible cable installation	≥ 75 mm
電纜直徑	10 mm
電纜結構	18x0,34 已屏蔽
導體的額定截面	0.34 mm ²
導線末端	導線末端套圈
防護等級	IP54
Note on degree of protection	裝配狀態
環境溫度	0 ... 40 °C
材料備註	含有 PWIS
耐腐蝕等級 CRC	0 - No corrosion stress