


# 保護罩 NECV-S1W37

料號: 545974

FESTO

用於閩島 VTSA 及 VTSA-F, 用於無電纜的內部組裝.

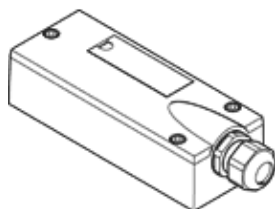

## 技術參數

特性	值
應用領域	Only for multi-pin plug connection valve terminal VTSA/VTSA-F
產品重量	180 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭插座
Electrical connection 1, cable outlet	Angled
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	37
Electrical connection 1, occupied pins/wires	37
Electrical connection 1, type of mounting	3x M4 screws
Electrical connection 2, connection technology	Crimp contacts
工作電壓範圍 DC	0 ... 30 V
在40°C時的可接受電流負載	2 A
浪湧強度	1 kV
電纜螺紋連接	M20x1,5
電纜直徑	5 ... 13 mm
導體的額定截面	0.08 ... 0.5 mm <sup>2</sup>
防護等級	IP65 NEMA 4
Note on degree of protection	裝配狀態
環境溫度	-5 ... 50 °C
PWIS conformity	VDMA24364-B1/B2-L
耐腐蝕等級 CRC	2 - Moderate corrosion stress
Material housing	PA