


# 塑料氣管 PLN

料號: 553850

FESTO

請注意最小訂購量.

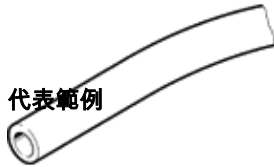

代表範例

## 技術參數

整體數據表 – 個別數值取決於您的配置.

特性	值
外徑	4 ... 16 mm
內徑	2.9 ... 12 mm
溫度取決於操作壓力	-0.95 ... 14 bar
授權	TÜV
認證核發部門	B 013277 0506 00
操作介質	壓縮空氣符合 ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at <a href="http://www.festo.com">www.festo.com</a>
PWIS conformity	VDMA24364-B1/B2-L
無塵室等級	This product is a static object, active particle generation is not possible when used correctly. Clean product before using it in a cleanroom environment and ensure it is installed correctly.
Food-safe	See Supplementary material information
環境溫度	-30 ... 80 °C
顏色	藍色 棕色 黃色 綠色 中性 紅色 黑色 銀 白色
材料備註	符合 RoHS
Material tubing	PE