

# 塑料氣管

## PUN-H-4X0,75-BL-500


料號: 558257

★ Kernprogramm

可用於食品加工行業 (耐水解).

This product is suitable for use with the fittings series types: QS, NPQP, NPQM, CRQS and CK.

FESTO

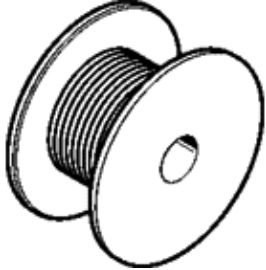

### 技術參數

特性	值
外徑	4 mm
與流量相關的彎曲半徑	16 mm
內徑	2.6 mm
最小彎曲半徑	8 mm
Instructions for use	TPE-U Ether basiert
Tubing characteristics	Suitable for energy chains
Operating pressure for entire temperature range	-0.095 ... 0.6 MPa
操作壓力的完整溫度範圍	-0.95 ... 6 bar
Operating pressure for entire temperature range	-13.775 ... 87 psi
Temperature-dependent operating pressure	-0.095 ... 1 MPa
溫度取決於操作壓力	-0.95 ... 10 bar
Temperature-dependent operating pressure	-13.775 ... 145 psi
操作壓力注意事項	Water: temperature-dependent operating pressure, see diagram, max. 0.3 MPa at 0 - 60°C
授權	TÜV
認證核發部門	B 013277 0506 00
操作介質	壓縮空氣符合 ISO8573-1:2010 [7:-:-] Water (liquid, free of ice)
Material fire test	UL94 HB
PWIS conformity	VDMA24364-B2-L
RSBP classification to CD-0033	F1a
無塵室等級	This product is a static object, active particle generation is not possible when used correctly. Clean product before using it in a cleanroom environment and ensure it is installed correctly.
Food-safe	See Supplementary material information
環境溫度	-35 ... 60 °C
產品重量視長度而定	0.0085 kg/m
氣壓連接	For push-in connector outside diameter 4 mm 用於倒鉤接頭內徑 3 mm 具螺母
顏色	藍色
肖氏硬度	D 52 +/-3
材料備註	符合 RoHS
Material tubing	TPE-U(PU)