

塑料氣管 PUN-H-8X1,25-SI


料號: 558280

★ Kernprogramm

可用於食品加工行業 (耐水解).

This product is suitable for use with the fittings series types: QS, NPQP, NPQM, CRQS and CK.

FESTO

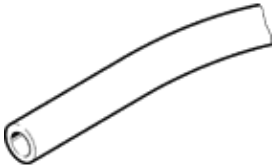

技術參數

| 特性 | 值 |
|---|--|
| 外徑 | 8 mm |
| 與流量相關的彎曲半徑 | 37 mm |
| 內徑 | 5.7 mm |
| 最小彎曲半徑 | 21 mm |
| Instructions for use | TPE-U Ether basiert |
| Tubing characteristics | Suitable for energy chains |
| Operating pressure for entire temperature range | -0.095 ... 0.6 MPa |
| 操作壓力的完整溫度範圍 | -0.95 ... 6 bar |
| Operating pressure for entire temperature range | -13.775 ... 87 psi |
| Temperature-dependent operating pressure | -0.095 ... 1 MPa |
| 溫度取決於操作壓力 | -0.95 ... 10 bar |
| Temperature-dependent operating pressure | -13.775 ... 145 psi |
| 操作壓力注意事項 | Water: temperature-dependent operating pressure, see diagram, max. 0.3 MPa at 0 - 60°C |
| 授權 | TÜV |
| 認證核發部門 | B 013277 0506 00 |
| 操作介質 | 壓縮空氣符合 ISO8573-1:2010 [7:-:-] Water (liquid, free of ice) |
| Material fire test | UL94 HB |
| PWIS conformity | VDMA24364-B2-L |
| RSBP classification to CD-0033 | F1a |
| 無塵室等級 | This product is a static object, active particle generation is not possible when used correctly. Clean product before using it in a cleanroom environment and ensure it is installed correctly. |
| Food-safe | See Supplementary material information |
| 環境溫度 | -35 ... 60 °C |
| 產品重量視長度而定 | 0.0287 kg/m |
| 氣壓連接 | For push-in connector outside diameter 8 mm 用於倒鉤接頭內徑 6 mm 具螺母 |
| 顏色 | 銀 |
| 肖氏硬度 | D 52 +/-3 |
| 材料備註 | 符合 RoHS |
| Material tubing | TPE-U(PU) |