


端板
VMPAL-EPL-SD25
 料號: 560938

FESTO

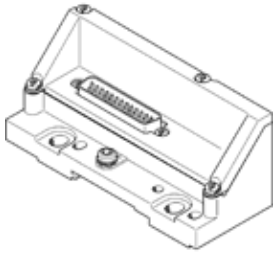

技術參數

特性	值
寬度	43 mm
長度	107.3 mm
閥位的最大數量	24
閥島結構	Valve sizes can be mixed
電磁線圈的最大數量	24
Operating pressure MPa	-0.09 ... 1 MPa
操作壓力	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
嚮導壓力	3 ... 8 bar
額定工作電壓 DC	24 V
耐腐蝕等級 CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
防護等級	IP67
Note on degree of protection	裝配狀態 with accessories VMPAL-KM
環境溫度	-5 ... 50 °C
產品重量	190 g
Electrical connection 1, function	Multi-pin插頭
Electrical connection 1, connection type	插頭
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	25
材料備註	符合 RoHS
Material end plate	壓鑄鋁 PA-加強