


# 塑料氣管 PUN-V0-8X2-WS-C

料號: 561715

FESTO

阻燃劑

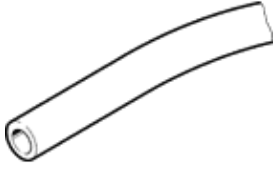

## 技術參數

| 特性  | 值   |
|---|---|
| 外徑  | 8 mm  |
| 與流量相關的彎曲半徑                                      | 35 mm   |
| 內徑  | 4 mm  |
| 最小彎曲半徑  | 9 mm  |
| Tubing characteristics                          | Suitable for energy chains  |
| Operating pressure for entire temperature range | -0.095 ... 1.2 MPa  |
| 操作壓力的完整溫度範圍                                     | -0.95 ... 12 bar  |
| Operating pressure for entire temperature range | -13.775 ... 174 psi   |
| Temperature-dependent operating pressure        | -0.095 ... 2 MPa  |
| 溫度取決於操作壓力                                       | -0.95 ... 20 bar  |
| Temperature-dependent operating pressure        | -13.775 ... 290 psi   |
| 操作壓力注意事項  | Water: max. 0.6 MPa at max. 50°C<br>For applications with welding spatter: max. 1 MPa at 20°C, max. 0.9 MPa at 40°C, max. 0.7 MPa at 60°C |
| 授權  | TÜV   |
| 認證核發部門  | B 013277 0506 00  |
| 操作介質  | 壓縮空氣符合 ISO8573-1:2010 [7:-:-]<br>Water (liquid, free of ice)  |
| Material fire test                              | UL94 V-0 (3mm)<br>UL94 V-2 (0,75mm)   |
| PWIS conformity                                 | VDMA24364-B2-L  |
| 環境溫度  | -35 ... 60 °C   |
| Note on ambient temperature                     | For unpressurised use up to 90 °C   |
| 產品重量視長度而定                                       | 0.049 kg/m  |
| 氣壓連接  | For push-in connector outside diameter 8 mm<br>用於倒鉤接頭內徑 4 mm  |
| 顏色  | 白色  |
| 關於顏色  | 由於高溫保護導致偏離標準色   |
| 肖氏硬度  | D 54 +/-3   |
| 材料備註  | 符合 RoHS   |
| Material tubing                                 | TPE-U(PU)   |