


擺動法蘭 SNGB-200-B

料號: 562455

FESTO

Suitable clevis foot LN, LSN in steel variant.

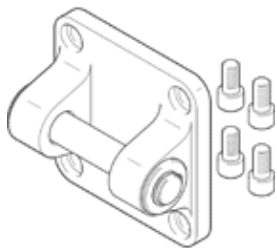

技術參數

特性	值
尺寸	200
基於標準	ISO 15552
耐腐蝕等級 CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
環境溫度	-40 ... 90 °C
產品重量	10,020 g
材料備註	符合 RoHS
Material mounting	鋼 經過電鍍
Material mounting pin	鋼, 鍍鋅
Material sleeve	鋼
Material bearing	塑料的
Material disc	鋼, 鍍鋅
Material screws	電鍍鋼
Material lock	彈簧鋼, 電鍍