


T形快插接頭 CRQST-1/4-1/4-U

料號: 565336
將停止供貨的產品

FESTO

Type to be discontinued. Available until 2024. See Support Portal for alternative products.

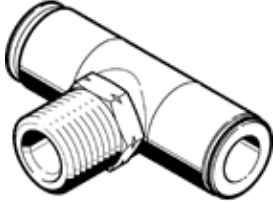

技術參數

| 特性 | 值 |
|---|--|
| 尺寸 | 標準 |
| 額定尺寸 | 0.217 " |
| 裝配位置 | 任何 |
| 設計 | T-形 |
| 容器尺寸 | 1 |
| 設計結構 | 推/拉原理 |
| Operating pressure for entire temperature range | -0.095 ... 1.4 MPa |
| 操作壓力的完整溫度範圍 | -0.95 ... 14 bar |
| Operating pressure for entire temperature range | -13.775 ... 203 psi |
| 操作介質 | 壓縮空氣符合 ISO8573-1:2010 [7:-:-] |
| 耐腐蝕等級 CRC | 4 - Very high corrosion stress |
| PWIS conformity | VDMA24364 zone III |
| Food-safe | See Supplementary material information |
| 環境溫度 | -20 ... 150 °C |
| 最大緊固扭矩 | 11.801 ft-lbf |
| 產品重量 | 1.185 oz |
| 可使用電線 | PFAN |
| 安裝類型 | External hex 35/64 |
| 氣壓連接, 氣口 1 | Male thread 1/4 NPTF |
| 氣壓連接, 氣口 2 | 用於1/4" 外徑的氣管 |
| Ambient temperature Fahrenheit | -4 ... 302 °F |
| 材料備註 | 符合 RoHS |
| Material housing | 高合金鋼, 耐腐蝕 |
| Material release ring | 高合金鋼, 耐腐蝕 |
| Material of tubing seal | FPM |
| Material of tube retaining claw | 高合金鋼, 耐腐蝕 |