


# 塑料氣管

## PUN-H-1/8-GN-150-CB

料號: 567977

FESTO

可用於食品加工行業 (耐水解).

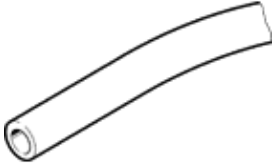

### 技術參數

| 特性                             | 值  |
|--------------------------------|--|
| 外徑, 英寸                         | 1/8  |
| 與流量相關的彎曲半徑                     | 0.039 ft   |
| 最小彎曲半徑                         | 0.02 ft  |
| Instructions for use           | TPE-U Ether basiert  |
| Tubing characteristics         | Suitable for energy chains   |
| 溫度取決於操作壓力                      | -14.4 ... 145 Psi  |
| 操作壓力注意事項                       | Water: temperature-dependent operating pressure, see diagram, max. 0.3 MPa at 0 - 60°C   |
| 操作介質                           | 壓縮空氣符合 ISO8573-1:2010 [7:-:-]<br>Water (liquid, free of ice)   |
| Material fire test             | UL94 HB  |
| PWIS conformity                | VDMA24364-B2-L   |
| RSBP classification to CD-0033 | F1a  |
| 無塵室等級                          | This product is a static object, active particle generation is not possible when used correctly.<br>Clean product before using it in a cleanroom environment and ensure it is installed correctly. |
| Food-safe                      | See Supplementary material information   |
| 環境溫度                           | -31 ... 145 °F   |
| 產品重量視長度而定                      | 0.06 oz/ft   |
| 氣壓連接                           | For push-in connector outside diameter 1/8"  |
| 顏色                             | 綠色   |
| 肖氏硬度                           | D 52 +/-3  |
| 材料備註                           | 符合 RoHS  |
| Material tubing                | TPE-U(PU)  |