
 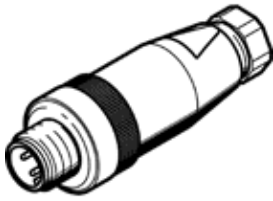


插頭

NECU-S-M12G4-P1-Q6-IS

料號: 570955

FESTO



技術參數

特性	值
基於標準	EN 61076-2-101 EN 61984
連接頻率	50
裝配位置	任何
產品重量	18 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	圓形
Electrical connection 1, connection type	插頭
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 1, number of pins/wires	4
Electrical connection 1, type of mounting	Screw-type lock with hex A/F 18 mm and longitudinal knurl
Electrical connection 2, connection type	電纜
Electrical connection 2, connection technology	螺紋介面
工作電壓範圍 DC	0 ... 30 V
在40°C時的可接受電流負載	4 A
浪湧強度	2.5 kV
電纜螺紋連接	Pg7
容許的電纜直徑	2.5 ... 2.9 mm
端子截面	0.14 ... 0.5 mm ²
防護等級	IP65 IP67
環境溫度	-25 ... 85 °C
PWIS conformity	VDMA24364-B2-L
材料備註	符合 RoHS
污染程度	3
Material housing	PA
Material of union nut	PA
Material electrical contact	黃銅 白銅塗層