


塑料氣管
PUN-H-5/16-NT-500-HA
 料號: 8003127

FESTO

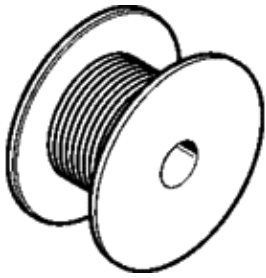

技術參數

特性	值
外徑, 英寸	5/16
與流量相關的彎曲半徑	0.123 ft
最小彎曲半徑	0.066 ft
Instructions for use	TPE-U Ether basiert
Tubing characteristics	Suitable for energy chains
溫度取決於操作壓力	-14.4 ... 145 Psi
操作壓力注意事項	Water: temperature-dependent operating pressure, see diagram, max. 0.3 MPa at 0 - 60°C
操作介質	壓縮空氣符合 ISO8573-1:2010 [7:-:-] Water (liquid, free of ice)
Material fire test	UL94 HB
PWIS conformity	VDMA24364-B2-L
RSBP classification to CD-0033	F1a
無塵室等級	This product is a static object, active particle generation is not possible when used correctly. Clean product before using it in a cleanroom environment and ensure it is installed correctly.
Food-safe	See Supplementary material information
環境溫度	-31 ... 145 °F
產品重量視長度而定	0.31 oz/ft
氣壓連接	For push-in connector outside diameter 5/16"
顏色	中性
肖氏硬度	D 52 +/-3
材料備註	符合 RoHS
Material tubing	TPE-U(PU)