


# 垂直壓力氣源板 VMPA2-VSP-QS1/4

料號: 8035442

FESTO

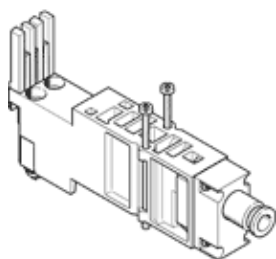

## 技術參數

特性	值
網柵尺寸	21 mm
Operating pressure MPa	-0.09 ... 1 MPa
操作壓力	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
嚮導壓力	3 ... 8 bar
操作介質	壓縮空氣符合 ISO8573-1:2010 [7:4:4]
耐腐蝕等級 CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
環境溫度	-5 ... 50 °C
產品重量	80 g
氣壓連接, 氣口 1	QS-1/4
材料備註	符合 RoHS
Material supply plate	PA-加強