
 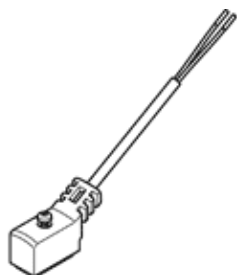


# 連接電纜

## NEBV-Z4WA2L-R-E-2.5-N-LE2-S1

料號: 8047679

FESTO



### 技術參數

| 特性   | 值  |
|--|--|
| Signal status display                          | 黃色 LED   |
| 附加功能   | 保持電流的降低<br>Protective circuit                          |
| Cable identification                           | Without inscription label holder                       |
| 連接頻率   | 50   |
| 產品重量   | 50 g   |
| Electrical connection 1, function              | Field device side                                      |
| Electrical connection 1, design                | 有角的  |
| Electrical connection 1, connection type       | 插頭插座   |
| Electrical connection 1, cable outlet          | Angled   |
| Electrical connection 1, connection technology | Connection pattern ZC, metric screw                    |
| Electrical connection 1, number of pins/wires  | 2  |
| Electrical connection 1, occupied pins/wires   | 2  |
| Electrical connection 1, type of mounting      | 通過M2中心螺絲安裝在電磁閥上  |
| Electrical connection 2, function              | Controller side  |
| Electrical connection 2, connection type       | 電纜   |
| Electrical connection 2, connection technology | 開放式終端  |
| Electrical connection 2, number of pins/wires  | 2  |
| Electrical connection 2, occupied pins/wires   | 2  |
| 工作電壓範圍 DC                                      | 20.4 ... 26.4 V  |
| 額定工作電壓 DC                                      | 24 V   |
| 浪湧強度   | 2.4 kV   |
| 極性保護   | 雙極   |
| 保護性接地  | 還未上市   |
| 電纜長度   | 2.5 m  |
| 電纜屬性   | Suitable for energy chains                             |
| 電纜的測試條件  | 視需求的測試條件   |
| Bending radius, flexible cable installation    | >= 29 mm   |
| 電纜直徑   | 2.9 mm   |
| 電纜直徑公差   | ± 0,1 mm   |
| 電纜結構   | 2x0,14   |
| 導體的額定截面  | 0.14 mm <sup>2</sup>                                   |
| 防護等級   | IP65   |
| Note on degree of protection                   | 裝配狀態   |
| 環境溫度   | -10 ... 50 °C  |
| CE 符號 (參見符合的標準)                                | 根據 EU-EMV 指導原則<br>in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity)   | To UK instructions for EMC<br>To UK RoHS instructions  |
| PWIS conformity                                | VDMA24364-B2-L   |
| 材料備註   | 符合 RoHS  |
| 污染程度   | 3  |
| 耐腐蝕等級 CRC                                      | 3 - High corrosion stress                              |
| Material cable sheath                          | TPE-U(PUR)   |
| 電纜外套顏色   | 灰色   |
| Material housing                               | TPE-U(PU)  |
| 外殼顏色   | 黑色   |
| Material screws                                | 不鏽鋼  |
| Material electrical contact                    | Copper alloy, tinned                                   |
| Material insulation                            | PP   |