
 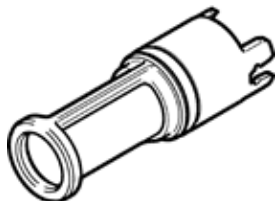


真空過濾器

OAFF-G3-7

料號: 8068945

FESTO



技術參數

特性	值
過濾等級	40 µm
容器尺寸	10
Operating pressure MPa	-95 ... 0 kPa
操作壓力	-0.95 ... 0 bar
Operating pressure	-13.775 ... 0 psi
操作介質	大氣基於 ISO 8573-1:2010 [7:-:-]
PWIS conformity	VDMA24364-B1/B2-L
產品重量	1.5 g
安裝類型	插上式 偵測
材料備註	符合 RoHS
Material seals	NBR
Material filter	網孔 PA
Material housing	POM
Ejector pulse suitability	0.7 MPa
噴射脈衝適用性	7 bar
Ejector pulse suitability (psi)	101.5 psi